


85906389 MG80C 60 Hz

DS/ISO-3743									
MG80C			85906389				D89		
[mm]									
P2:	1.1	[kW]	U:	440	[V]	2	:	60	[Hz]
3dB									

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	48,1	56,4	59,1	58,2	60,8	56,6	52,2	65,3	65,8
1m, re:20 Upa	36,3	44,6	47,3	46,4	49,0	44,8	40,4	53,5	54,0

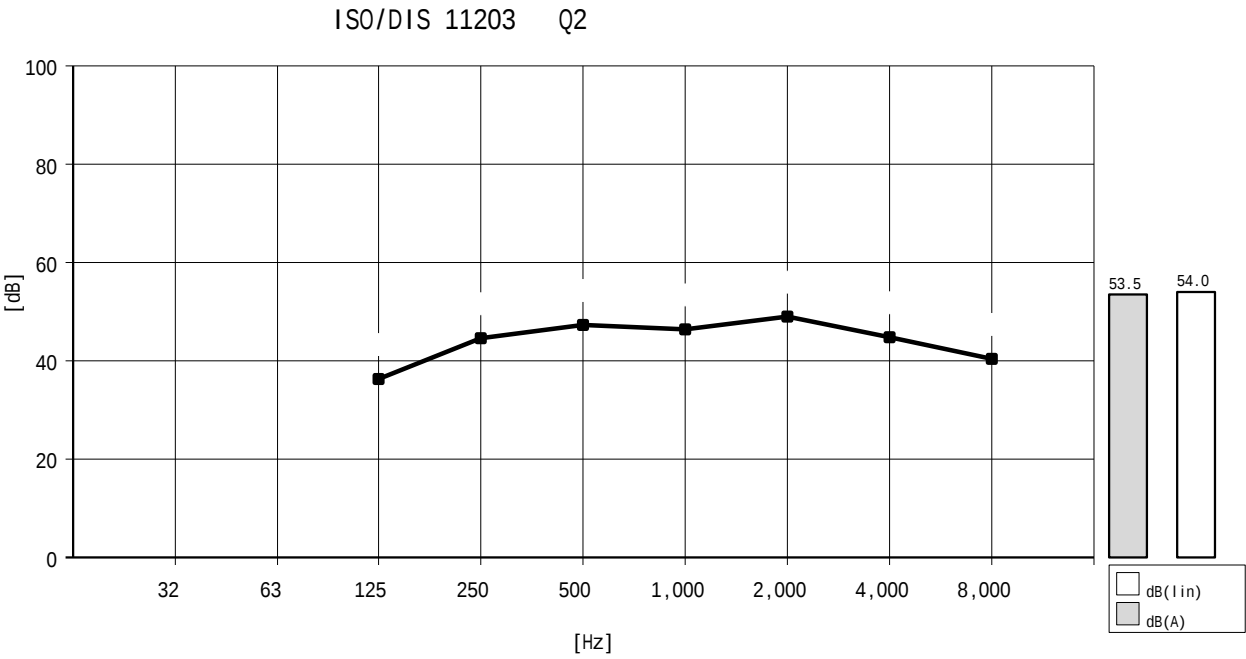

: KIR : LY15628-27.09.2006