


85900548 MG132SC 60 Hz

DS/ISO-3743									
MG132SC			85900548				D128		
							[mm]		
P2:	5.5	[kW]	U:	440	[V]	2	:	60	[Hz]
3dB									

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	66,3	68,7	71,3	72,3	68,8	65,3	57,4	76,0	77,3
1m, re:20 Upa	54,0	56,4	58,9	60,0	56,5	53,0	45,1	63,6	65,0

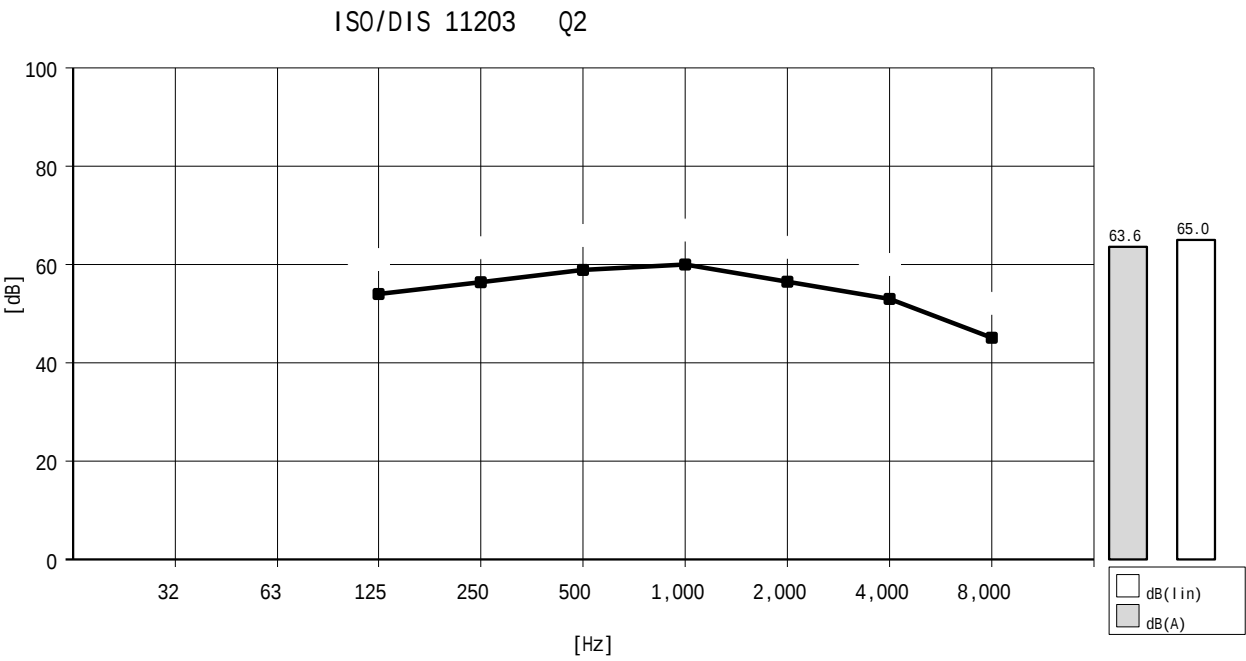

: KIR : LY15844-13.10.2006