

85904115 MG132SC 60

DS/ISO-3743			
:	MG132SC	:	85904115
:		:	D128
P2:	5.5	U:	440 [V]
:		:	2
:		:	60 [Hz]


: 3 dB

:

[db]

	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re1 pW	66,3	68,7	71,3	72,3	68,8	65,3	57,4	76,0	77,3
1m re 20 UPa	54,0	56,4	58,9	60,0	56,5	53,0	45,1	63,6	65,0

ISO/DIS 11203 Q2

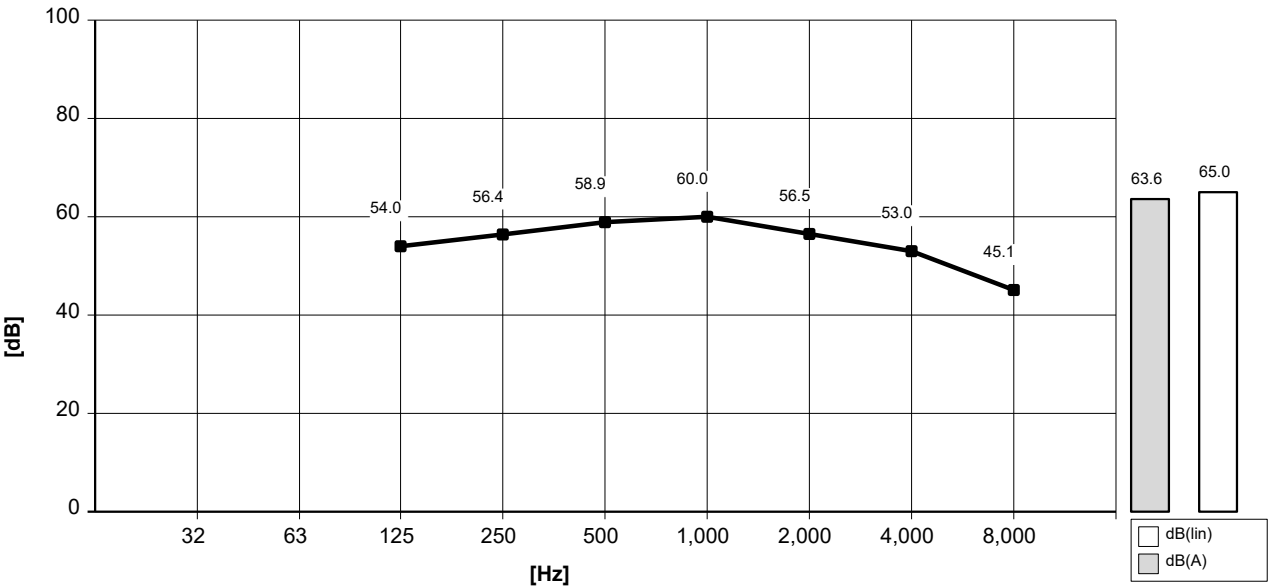

: KIR : LY15844-13.10.2006