


87220360 MG90LC 60 Hz

DS/ISO-3743									
MG90LC			87220360				D108		
							[mm]		
P2:	2.2	[kW]	U:	440	[V]	2		60	[Hz]
3dB									

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	62,5	63,5	66,1	67,0	66,4	61,5	55,8	71,8	72,9
1m, re:20 Upa	50,5	51,5	54,1	55,0	54,4	49,5	43,8	59,8	60,8

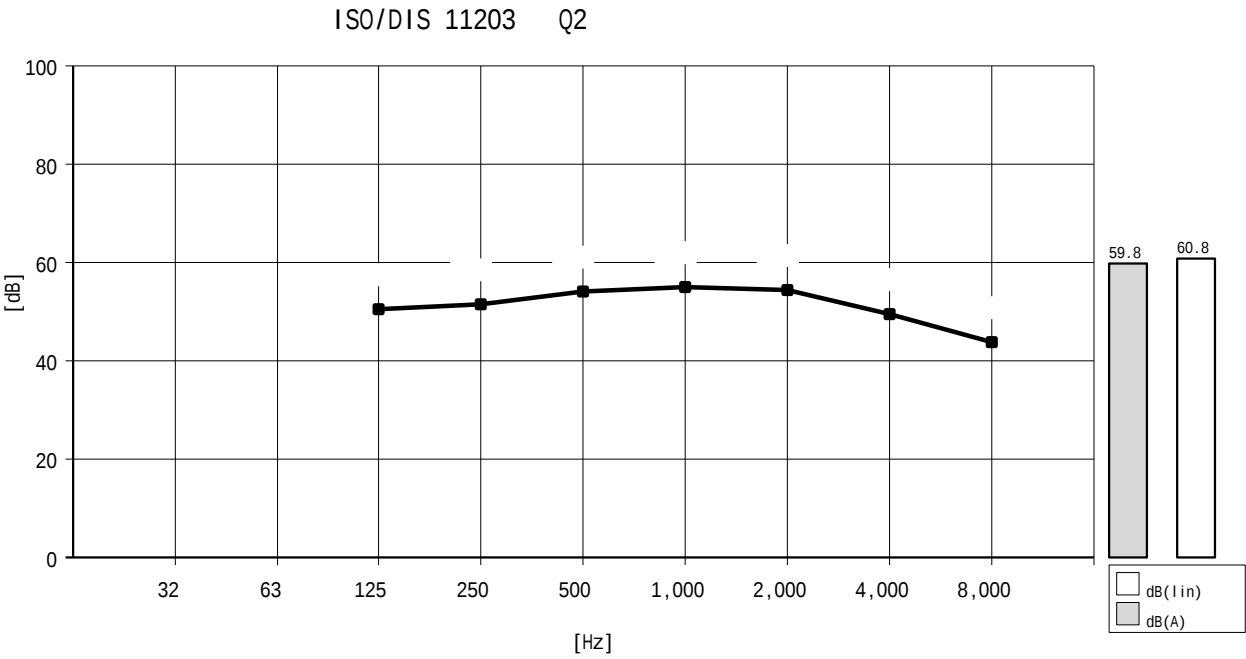

: KIR : LY15670-29.09.2006