


85805102 MG71A 60 Hz

DS/ISO-3743																	
MG71A		85805102				D89											
						[mm]											
P2:	0.37		U:	440		2		60									
						[kW]											
						[V]											
						[Hz]											
3dB																	

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	48,2	58,2	57,5	57,9	61,0	56,5	51,7	65,2	65,7
1m, re:20 Upa	36,5	46,4	45,8	46,2	49,2	44,8	40,0	53,5	54,0

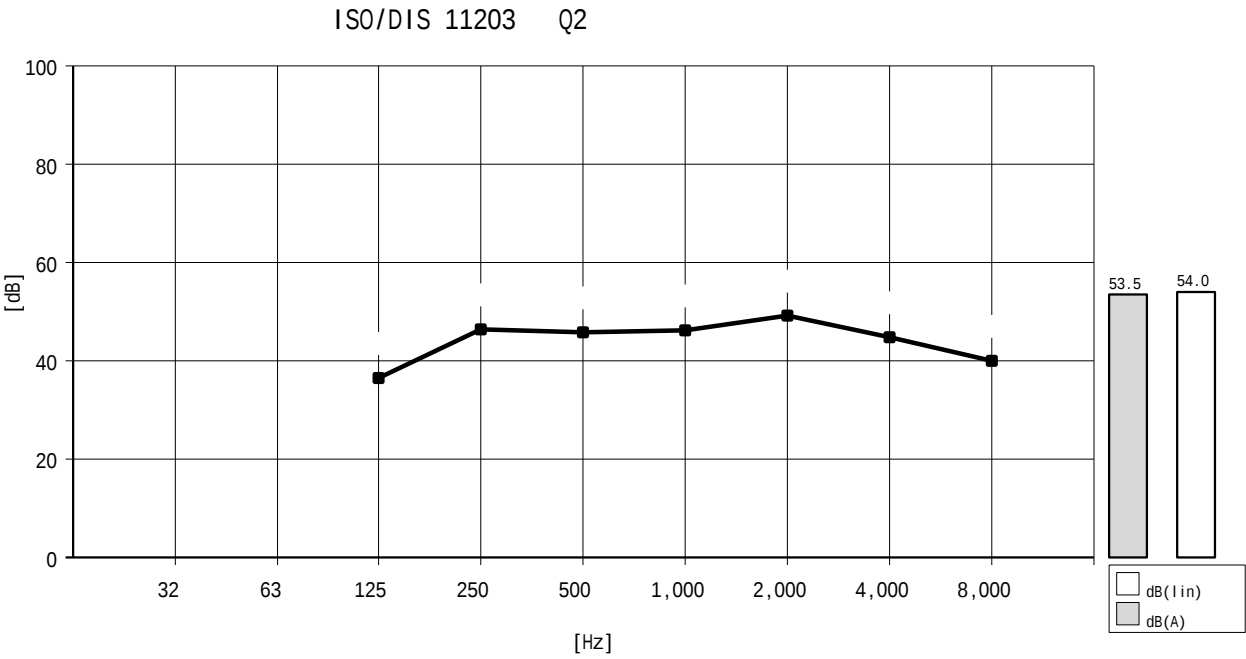

: KIR : LY15608-27.09.2006