


85324104 MG80A 60 Hz

DS/ISO-3743									
MG80A			85324104				D89		
[mm]									
P2:	0.75	[kW]	U:	440	[V]	2		60	[Hz]
3dB									

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	48,8	56,4	59,1	59,7	60,6	56,5	52,2	65,5	66,0
1m, re:20 Upa	37,0	44,6	47,2	47,9	48,7	44,7	40,4	53,7	54,2

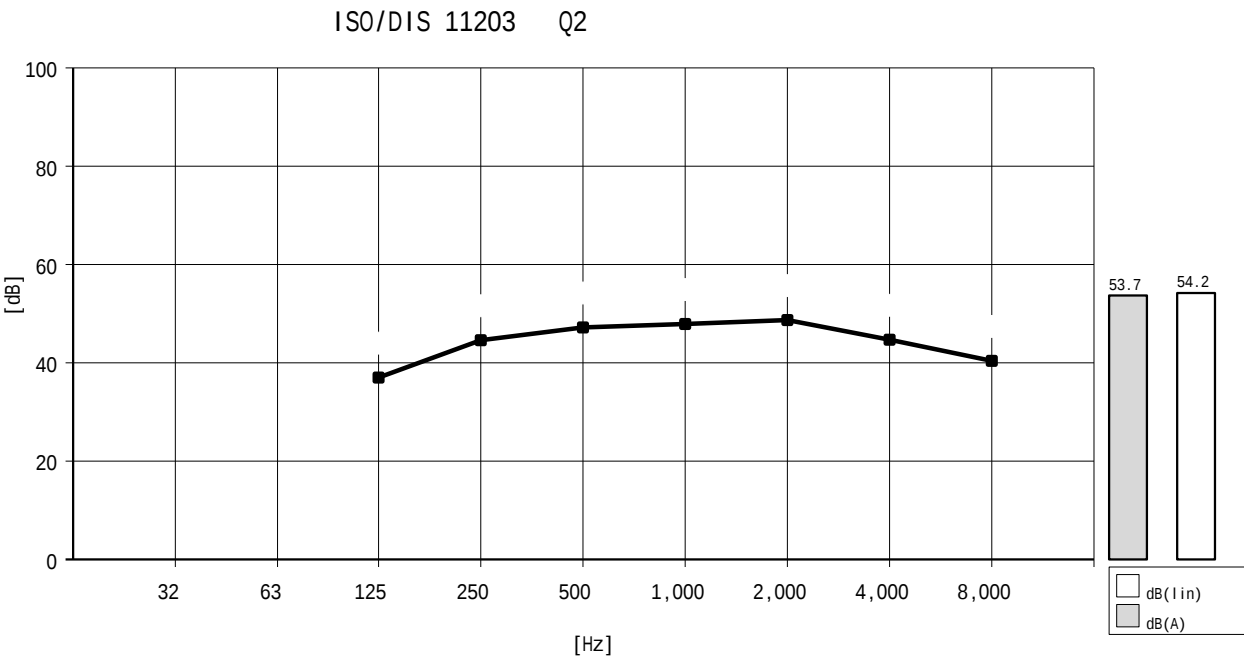

: KIR : LY15641-28.09.2006