


85905176 MG80C 60 Hz

DS/ISO-3743																	
MG80C			85905176				D89										
							[mm]										
P2:	1.1			U:	440			2	60								
		[kW]				[V]		[Hz]									
3dB																	

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	48,1	56,4	59,1	58,2	60,8	56,6	52,2	65,3	65,8
1m, re:20 Upa	36,3	44,6	47,3	46,4	49,0	44,8	40,4	53,5	54,0

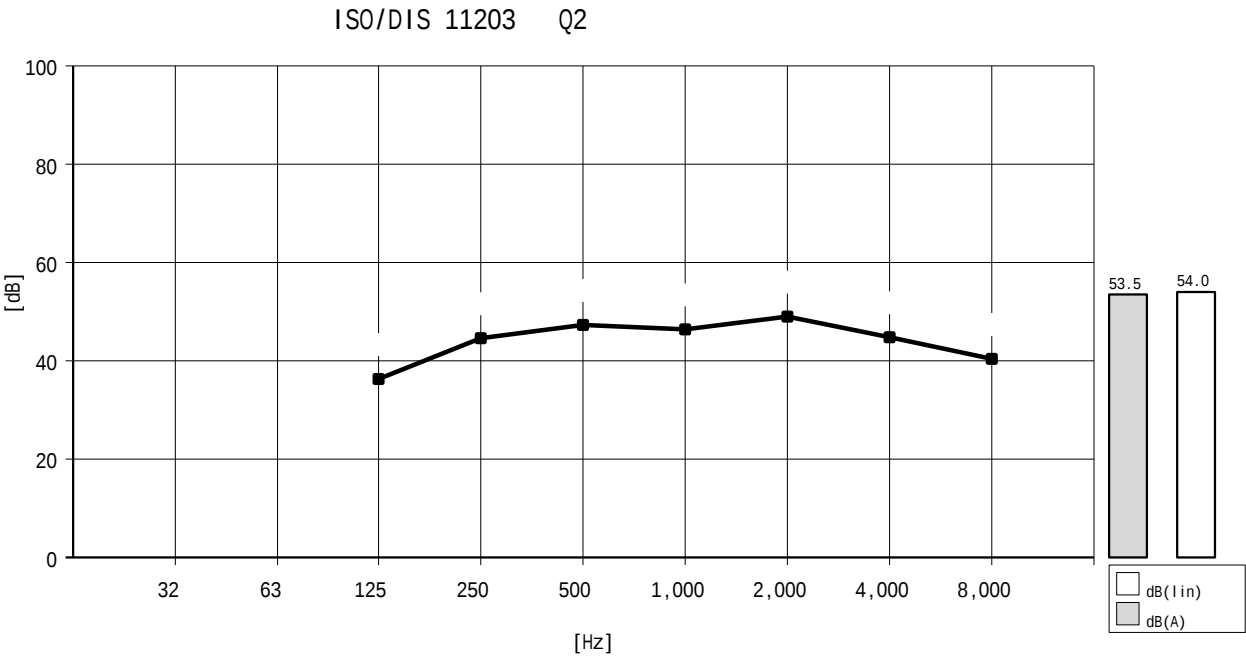

: KIR : LY15628-27.09.2006