


85903412 ML160AB 60 Hz

DS/ISO-3743									
ML160AB			85903412				D210 [mm]		
P2:	15 [kW]	U:	440 [V]		2			60 [Hz]	
3dB									

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	63,8	68,0	74,1	72,8	71,0	68,2	64,8	77,7	78,8
1m, re:20 Upa	51,3	55,5	61,6	60,3	58,5	55,7	52,3	65,2	66,3

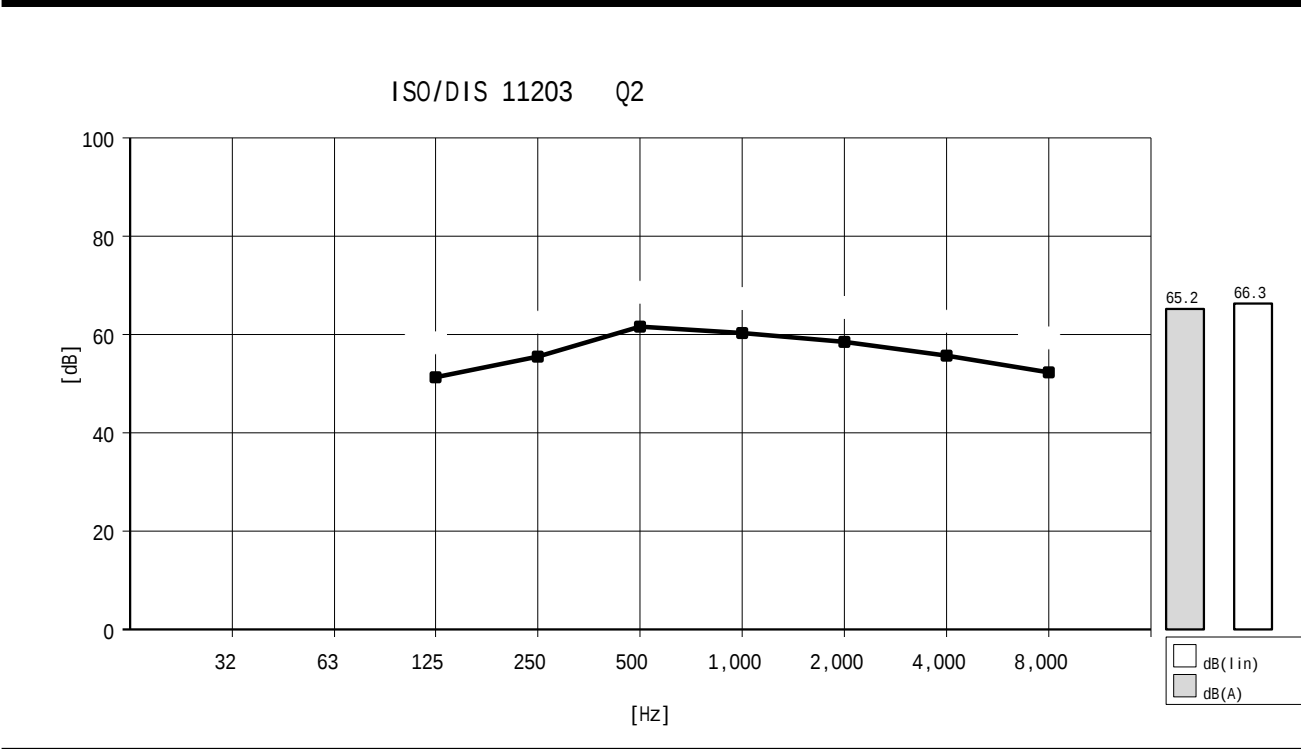

KIR									
LY 27.06.2008									