


87100356 MG80B 60 Hz

DS/ISO-3743									
MG80B		87100356				D89			
P2: 1.1		U: 440		2		60			
[kW]		[V]				[mm]			
				3dB					

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	43,5	53,6	52,3	53,8	56,1	51,7	46,7	60,4	61,0
1m, re:20 Upa	31,7	41,7	40,5	42,0	44,2	39,9	34,9	48,6	49,2

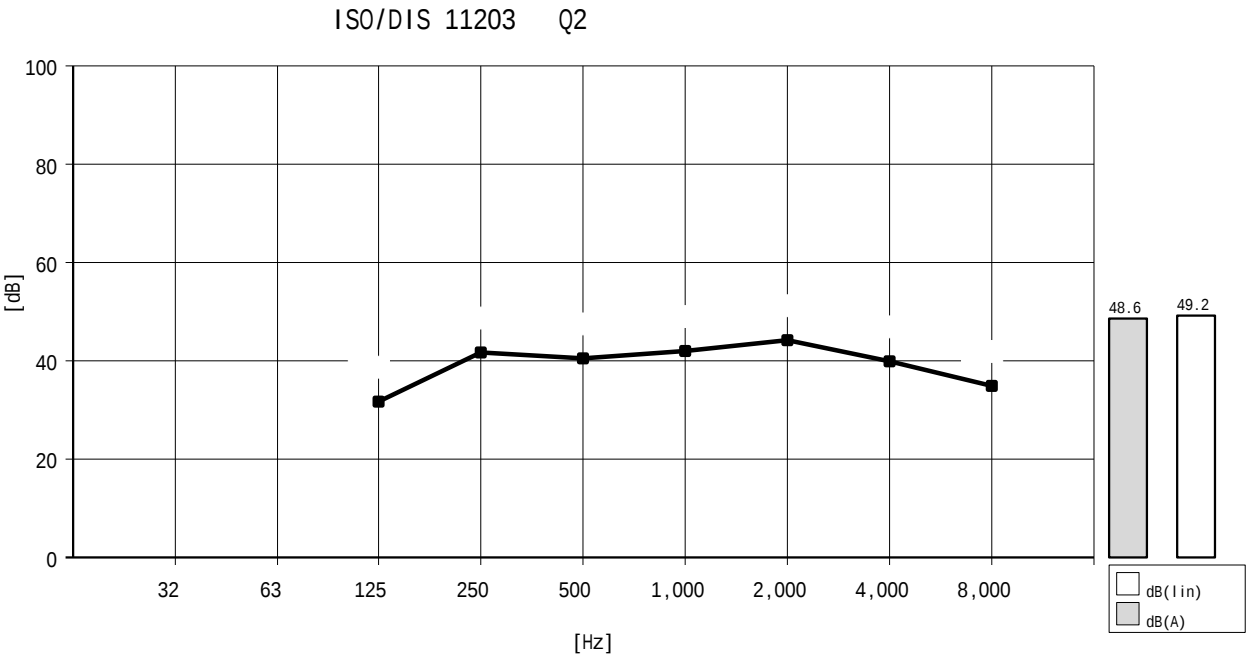

: KIR : LY15628-27.09.2006