


85905878 MG160LB 60 Hz

DS/ISO-3743									
MG160LB		85905878				D210		[mm]	
P2:	18.5	[kW]	U:	440	[V]	2	:	60	[Hz]
3dB									

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	66,9	68,4	73,6	73,2	70,5	69,0	65,7	77,8	78,9
1m, re:20 Upa	54,4	55,9	61,1	60,7	58,0	56,5	53,2	65,3	66,4

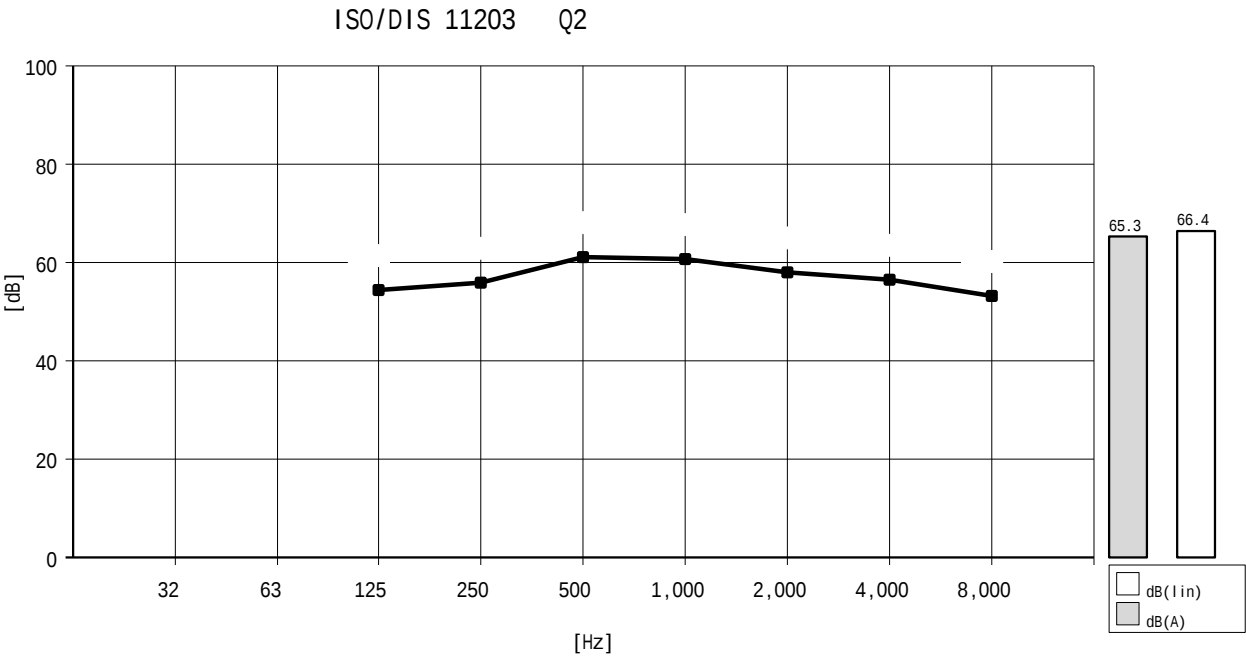

: KIR : LY 27.06.2008