


85905106 MG90LC 60 Hz

DS/ISO-3743
 MG90LC 85905106 D108 [mm]
 P2: 2.2 [kW] U: 440 [V] 2 60 [Hz]
 3dB

	[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)	
re:1 pW	62,5	63,5	66,1	67,0	66,4	61,5	55,8	71,8	72,9	
1m, re:20 Upa	50,5	51,5	54,1	55,0	54,4	49,5	43,8	59,8	60,8	

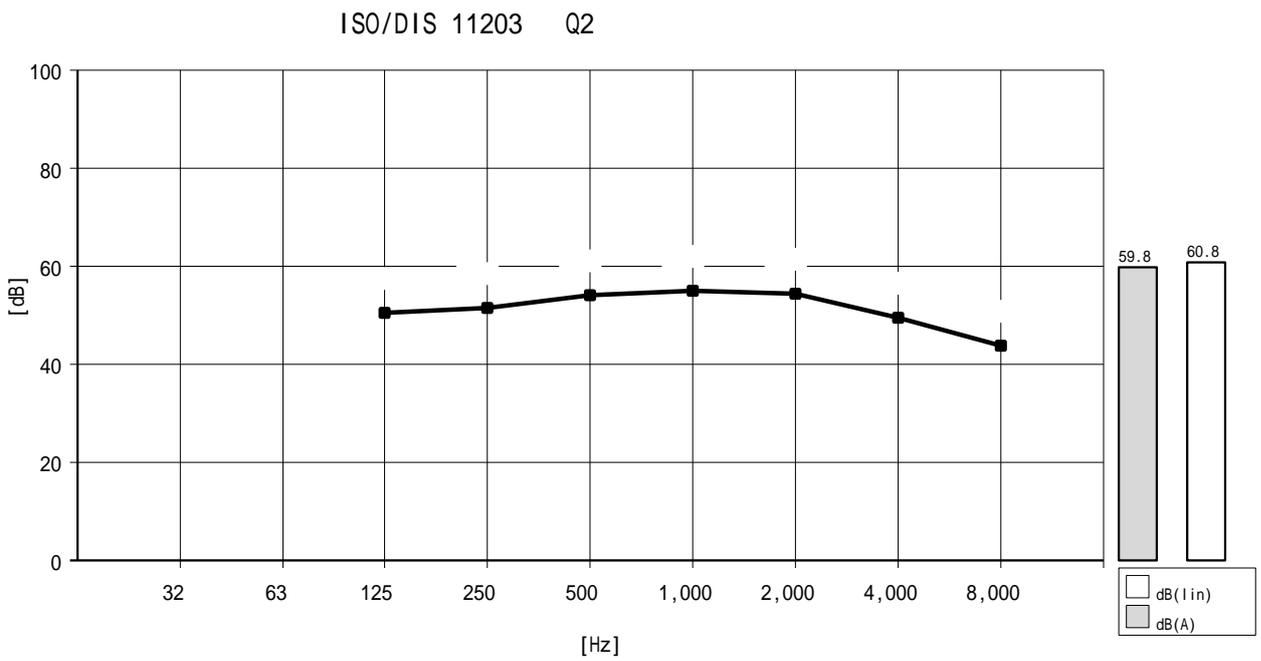

: KIR : LY15670-29.09.2006