


87272365 MG100LC 60 Hz

		DS/ISO-3743			
MG100LC		87272365		D108 [mm]	
P2:	3 [kW]	U:	440 [V]	2	60 [Hz]
3dB					

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	57,5	63,1	66,5	67,3	65,6	62,8	56,0	71,8	72,6
1m, re:20 Upa	45,5	51,1	54,5	55,3	53,6	50,7	44,0	59,8	60,6

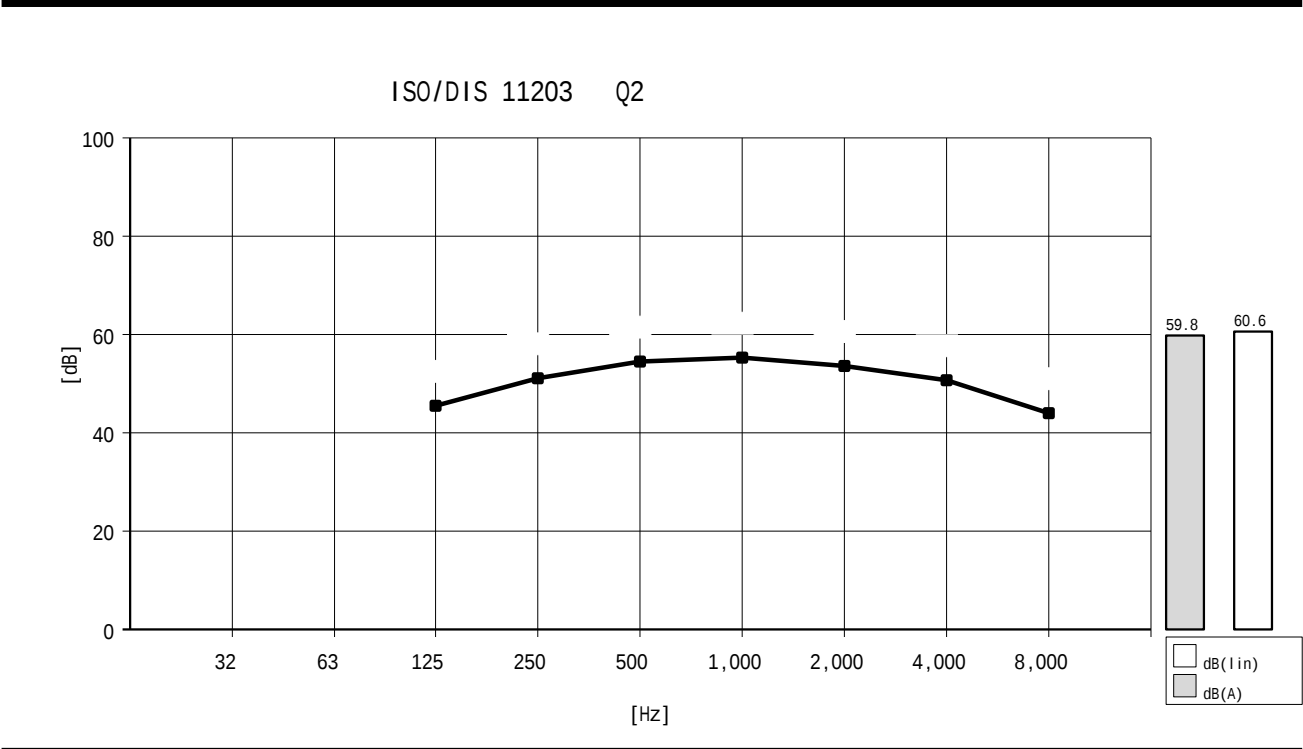

KIR		LY15656-29.09.2006			