


87312301 MG112MC 60 Hz

DS/ISO-3743									
MG112MC			87312301				D128		
							[mm]		
P2:	4	[kW]	U:	440	[V]	2		60	[Hz]
3dB									

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	66,2	68,8	71,2	72,0	68,9	65,7	58,5	75,9	77,2
1m, re:20 Upa	53,9	56,5	58,9	59,7	56,7	53,4	46,2	63,6	65,0

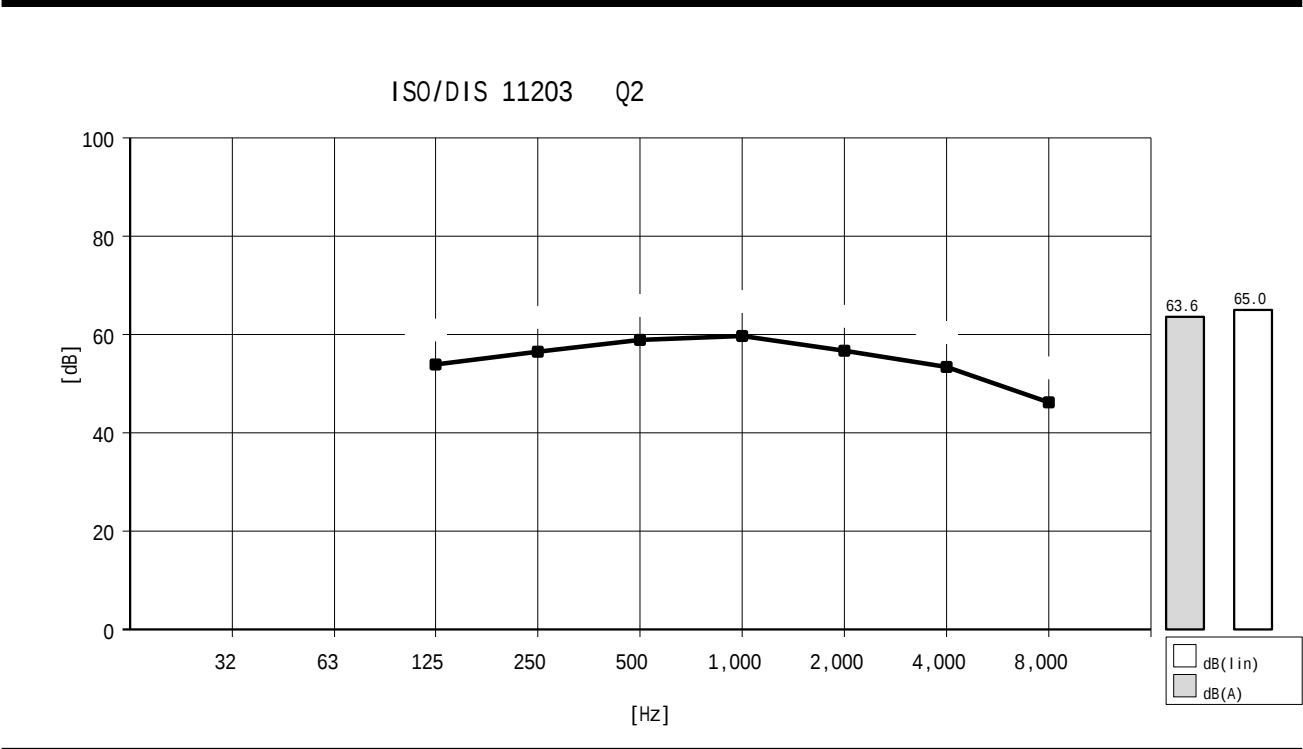

KIR									
LY15890-16.10.2006									