


86905654 MG71B 60 Hz

DS/ISO-3743									
MG71B		86905654				D124		[mm]	
P2:	0.37		U:	440		4		60	[Hz]
3dB									

[db]									
	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
re:1 pW	42,4	42,7	45,1	47,5	48,9	44,0	33,3	53,2	53,6
1m, re:20 Upa	30,7	31,0	33,4	35,8	37,2	32,3	21,5	41,5	41,9

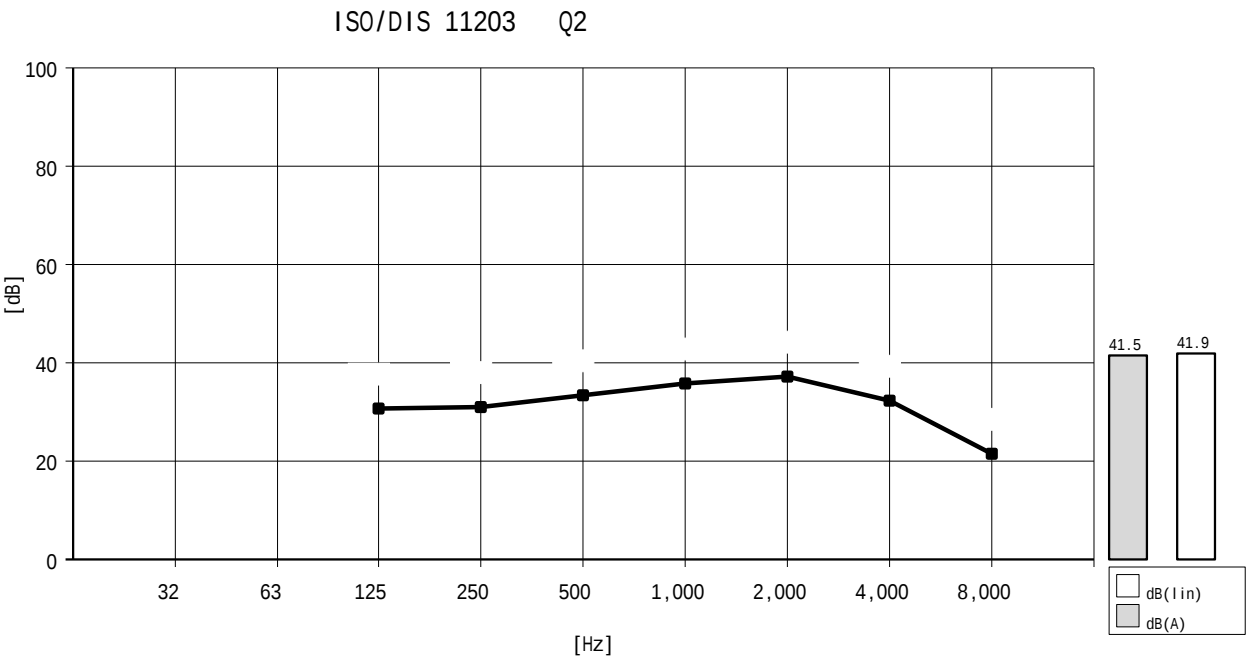

: KIR : LY20114-27.11-2007