

92696830 MG71A 50 Hz

Sound Measurement Report Sound Power measurement according to DS/ISO-3743

Motor type: MG71A Product number: 92696830 Fan diameter: D89 [mm]
P2: 0.25 [kW] U: 234 [V] Pole: 2 Frequency: 50 [Hz]


Remarks: The declared noise emission value, does not take production variations and measurement uncertainties into account. The declared value may therefore be up-to 3 dB higher, than the value for the average production unit.

Tested at: 2994 (idle) rpm

Octave Band Level [db]

Center Frequency	125	250	500	1000	2000	4000	8000	dB(A)	dB(lin)
Sound Power Level re: 1 pW	-	-	-	-	-	-	-	65,5	-
Sound Pressure Average at 1m. re: 20 UPa	23,3	37,1	42,5	49,8	49,9	43,9	35,2	54,0	-

Sound Pressure calculated according to ISO/DIS 11203 method Q2

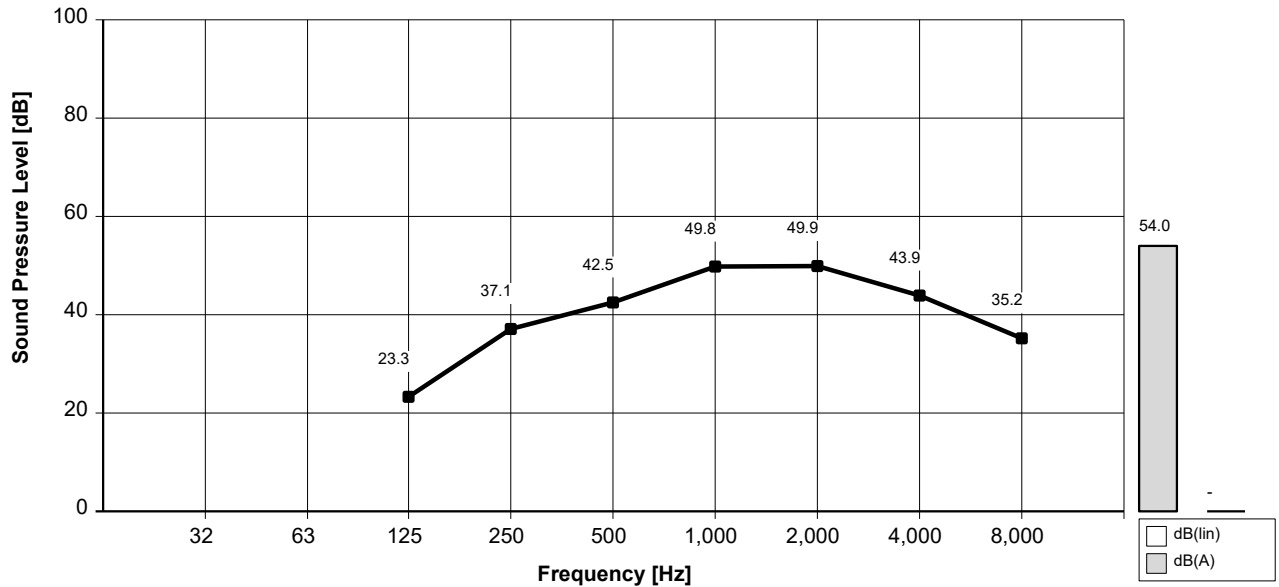

Initials: VBJ

File no.: LY76165 20/06/2022