

35. KPC

KPC 24/7, 300A, 600A

50/60 Hz

Cable

Pos.	Description	50/60 Hz				
		KPC 24/7, 300A		KPC 24/7, 300A, 600A		KPC 600A
		Kit No	97825411	98519587	97825435	98519592
	Plug type	Australia	Schuko	Australia	Schuko	
181	Cable, 10 m	1	1	1	1	
250	Cable entry	1	1	1	1	
250a	Cable relief	1	1	1	1	
48a	O-ring	1	1	1	1	
48b	Cable crimp	3	3	3	3	

Capacitor

Pos.	Description	50 Hz	60 Hz	50 Hz	60 Hz
		KPC 24/7, 300A		KPC 600A	
		Kit No	98520308	98520323	98520327
161	Capacitor	1	1	1	1
48b	Cable crimp	4	4	4	4

Fitting (Outlet)

Pos.	Description	50/60 Hz
		KPC 24/7, 300A, 600A
		Kit No
149b	Fitting 1 1/4"	1

Float switch

Pos.	Pump type	Frequency	KPC
			50/60 Hz
			Kit No
182	Float switch	1	1
250	Cable entry	1	1
250a	Cable relief	1	1
48a	O-ring	1	1
48b	Cable crimp	4	4


Impeller

Pos.	Description	50 Hz		60 Hz	
		KPC 24/7, 300A	KPC 600A	KPC 24/7, 300A	KPC 600A
		Kit No	98520216	98520232	98520220
49	Impeller	1	1	1	1
67	Nut	1	1	1	1
66	Wear ring disc	1	1	1	1

Strainer


Pos.	Description	50/60 Hz		
		KPC 24/7	KPC 300A	KPC 600A
		Kit No	98520428	98520425
84	Strainer	1	1	1

KPC 300A

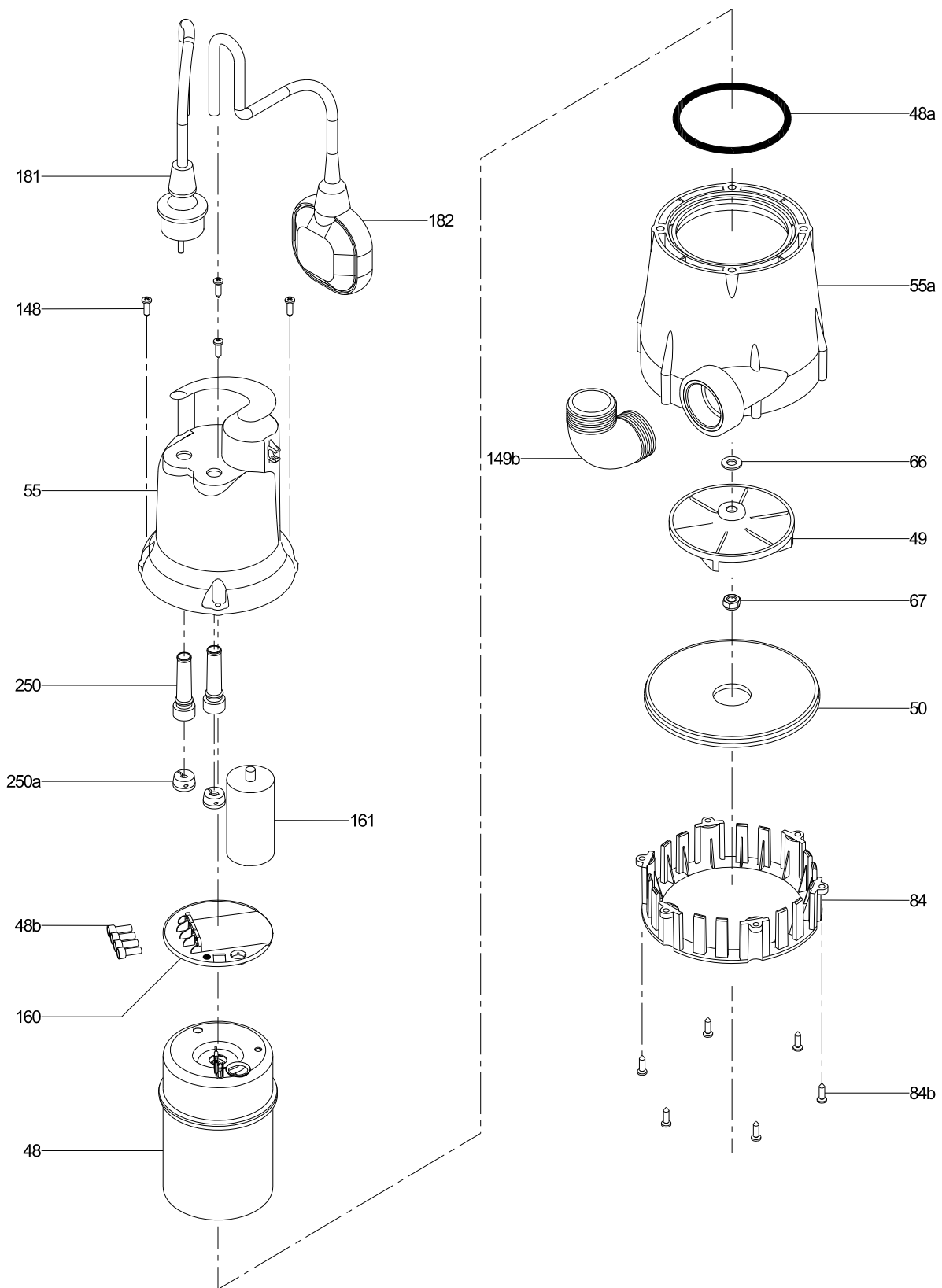


TM059721

KPC 600A

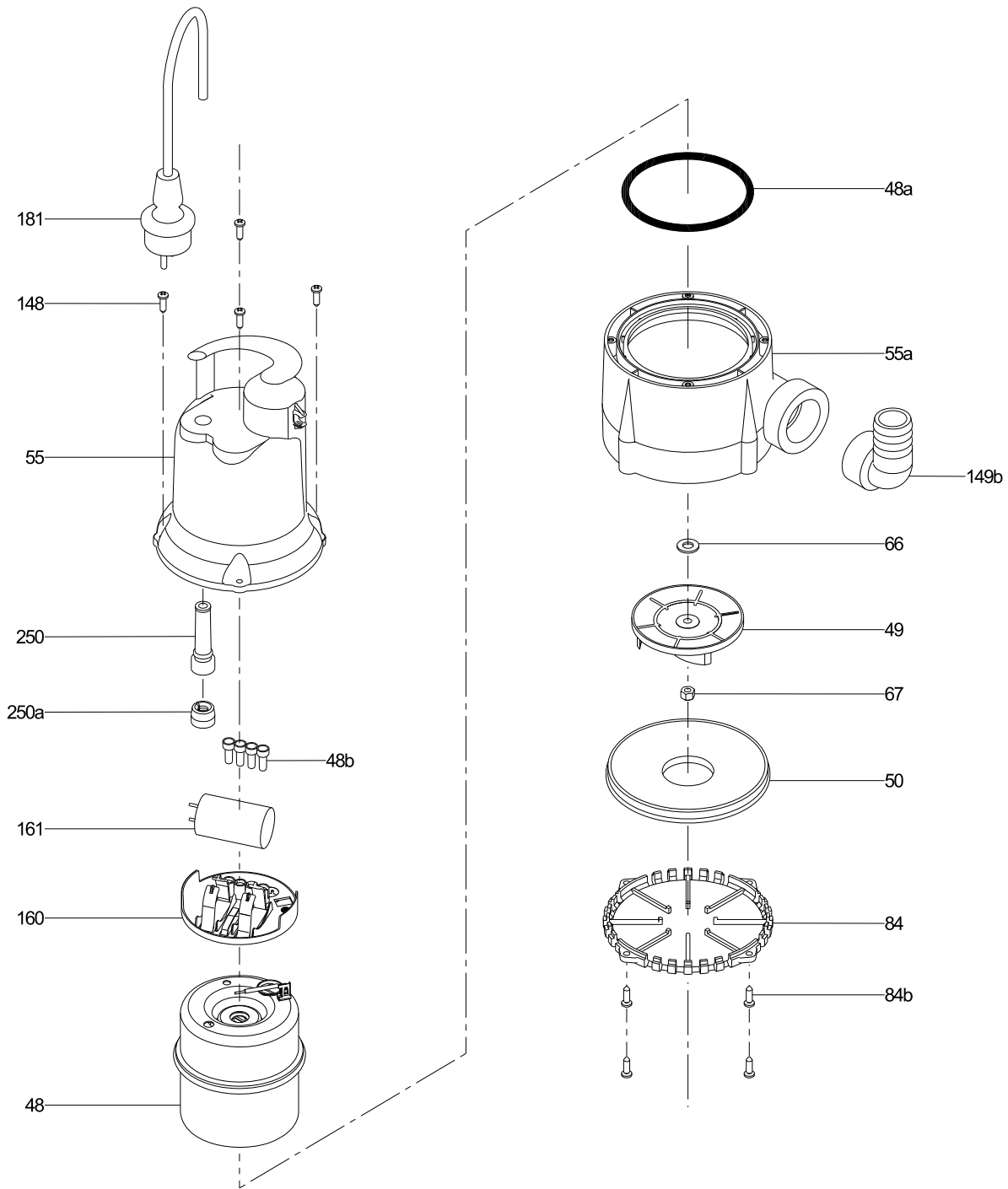

TM059720

KPC 24/7

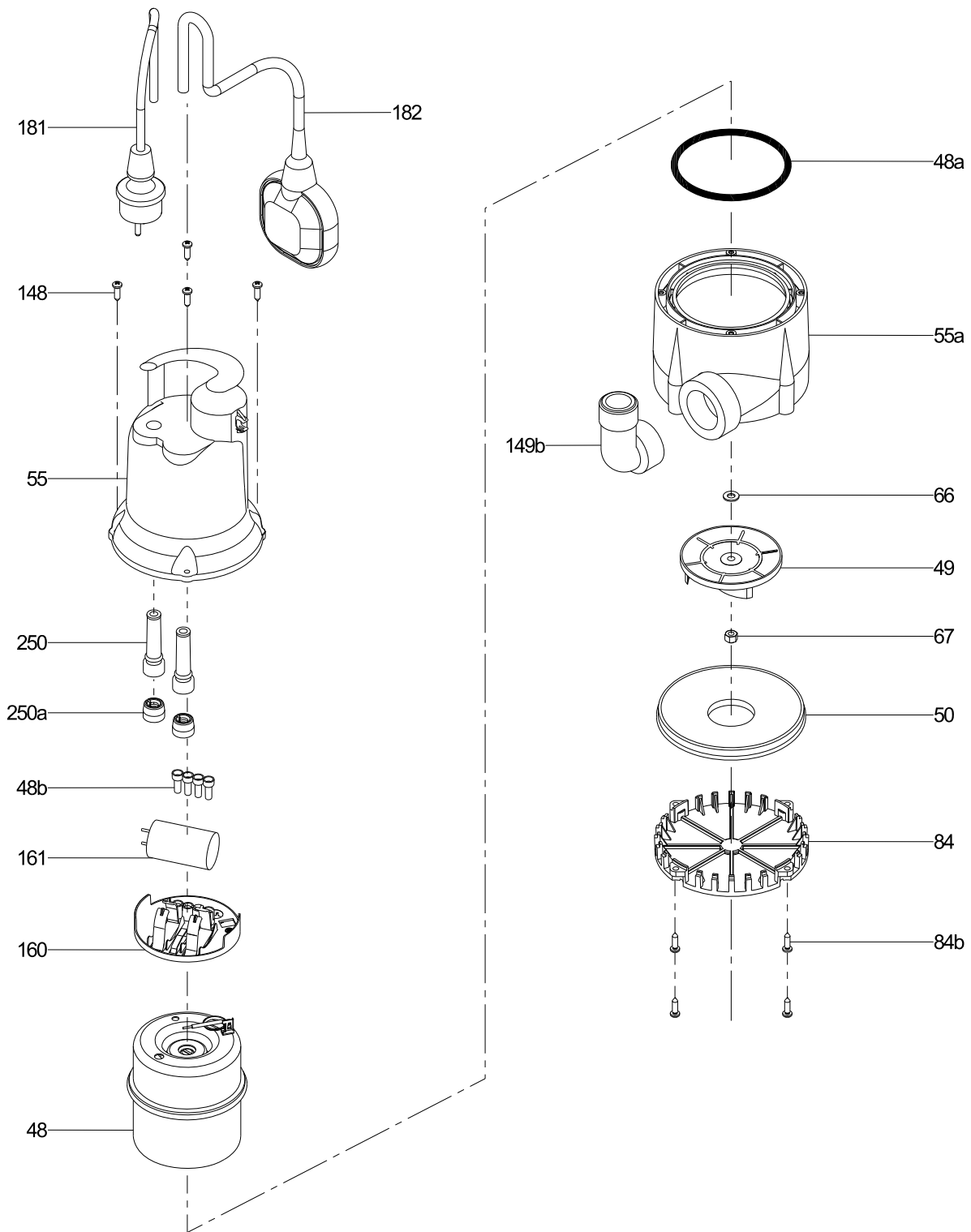

TM059719