

## 33. Hydro Solo E / S

### 50 Hz

#### Manometer kit

Pos.	Pump type	Hydro Solo E / S	
	Kit No	97896856	97896855
3	Manometer 10 bar	1	-
	Manometer 16 bar	-	1

#### Non return valve kit


Pos.	Pump type	Hydro Solo E / S				
	Kit No	96637443	96637444	96637445	98995447	98995448
8	Non return valve DN 32	1	-	-	-	-
	Non return valve DN 40	-	1	-	-	-
	Non return valve DN 50	-	-	1	-	-
	Non return valve DN 65	-	-	-	1	-
	Non return valve DN 80	-	-	-	-	1

#### Sensor kit


Pos.	Pump type	Hydro Solo E / S	
	Kit No	96637452	96637453
7	Pressure transducer 0 - 10 bar	1	-
	Pressure transducer 0 - 16 bar	-	1
-	Cable clip	1	1

#### Tank kit

Pos.	Pump type	Hydro Solo E / S	
	Kit No	98995462	98995463
2	Tank 18 liter, PN 10	1	-
	Tank 12 liter, PN 16	-	1

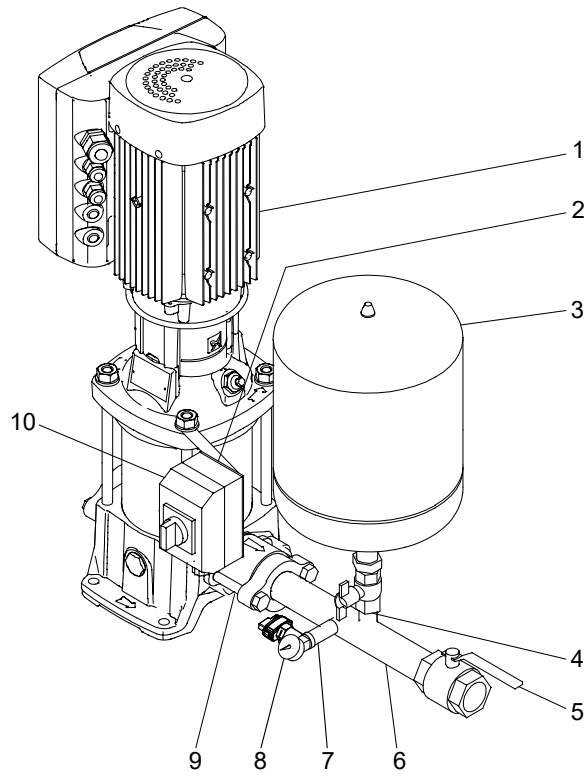

TM027562

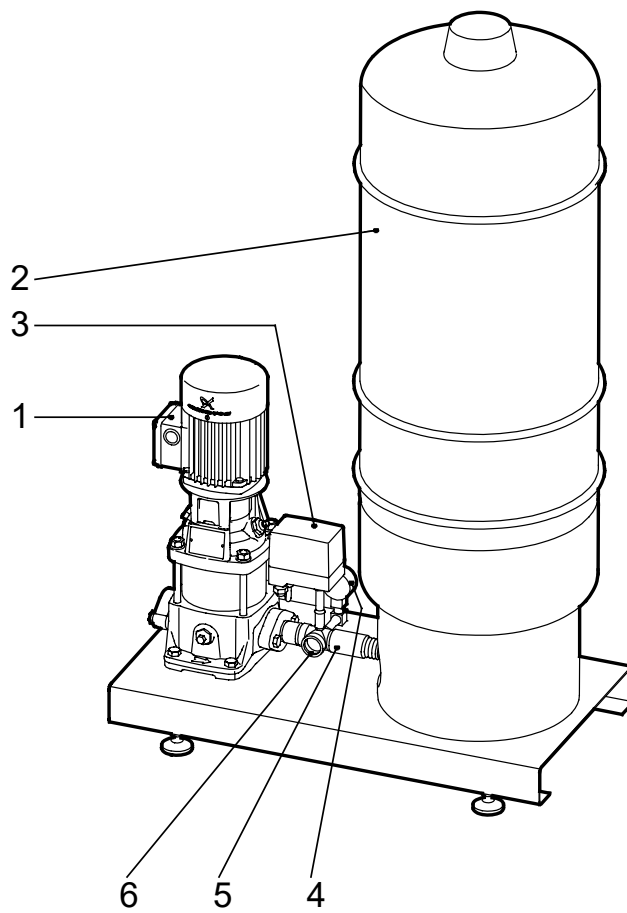

TM022587