

UPA 15-90 N

IMPROVE YOUR COMFORT WITH UPA HOME BOOSTER

The Grundfos **UPA** is a compact domestic pressure booster pump that will deliver the required pressure to hot or cold water taps, a shower or any other water outlet around the home.



WHY CHOOSE UPA 15-90 N?

- Helps to improve flow and pressure in domestic cold and hot water gravity fed systems.
- Canned rotor construction offers many benefits, including limiting operational noise (less than 43 dBA) and with only one gasket required to seal the unit, leakage is not an issue.
- Automatic operation - in AUTO mode the pump is operated via a built-in flow switch which means it runs only when needed.
- Plug and pump solution – supplied with pre wired lead and plug for ease of installation.

UPA 15-90 N

APPLICATION AND PERFORMANCE DATA



PRODUCT CODE 99539153

APPLICATIONS

- Residential installations where higher pressure is needed in taps, a shower, or other domestic water outlet connected to a storage tank
- Boosting of hot or cold water supply

Installation must comply with UK Water Regulations.

PERFORMANCE DATA

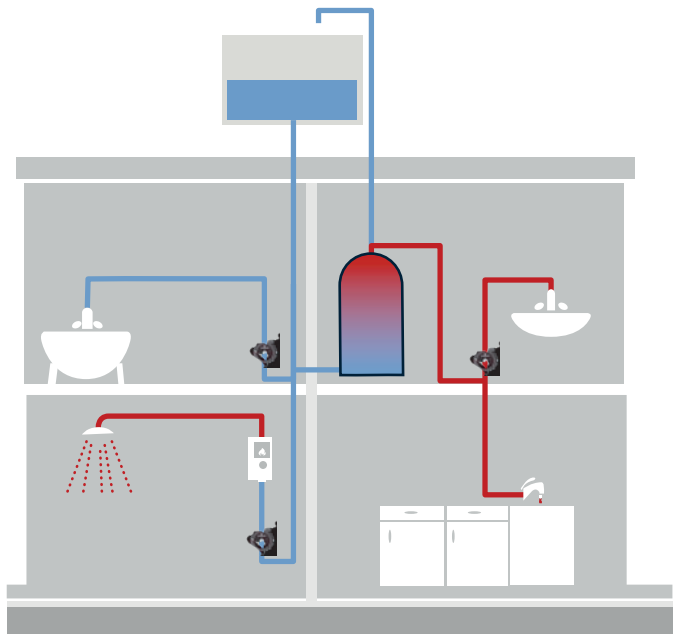
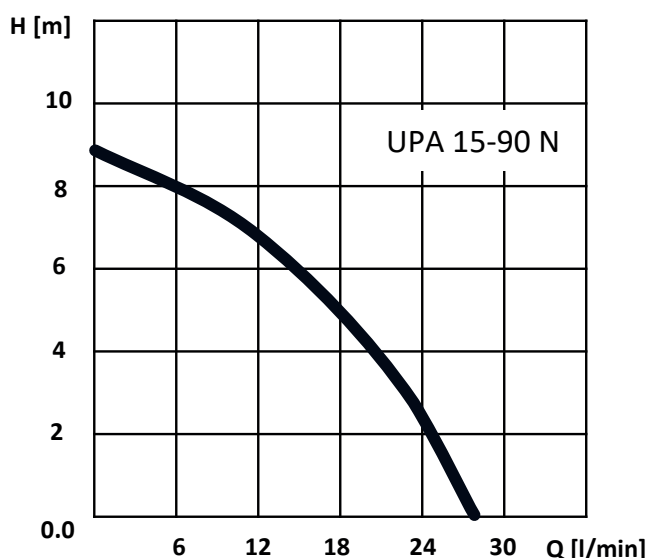


Illustration does not show non-return valves.

TECHNICAL DATA

Product code	99539153
Liquid temperature	+2 to +95 °C
Head max	9 m
Flow max	26 l/min
System pressure max	10 bar
Port to port	160 mm
Pump connections	G ¾ "
Union connection	R ½ "
Operation modes	Manual/Auto/Off
Power (P1)	120 W
Pump housing	Stainless steel
Flow switch	Integrated

99713900 0819
ECM: 1267558

For information information the UPA 15-90 N visit
www.grundfos.co.uk

Grundfos Pumps Ltd
Grovebury Road, Leighton Buzzard,
Beds. LU7 4TL
Tel: 01525 850000
Email: grundfos-uk@sales.grundfos.com
www.grundfos.co.uk

GRUNDFOS