

Quick selection guide | Grundfos domestic cold water

Perfect water pressure

Just when you need it

















SOLOLIFT2 range



Possibility in every drop

Lifting Stations


 

● Fixed inlet ○ Additional optional inlet

	 SOLOLIFT2 WC-1	 SOLOLIFT2 WC-3	 SOLOLIFT2 D-2	 SOLOLIFT2 C-3	 SOLOLIFT2 CWC-3
 Toilet	●	●			
 Wall-mounted toilet					●
 Urinal	○	○			○
 Sink	○	○	○	○	○
 Bidet		○	○	○	○
 Shower		○	○	○	○
 Bathtub				○	
 Washing machine				○	
 Kitchen sink				○	
 Dish-washer				○	
 Water softener				○	

Lifting Stations – Quick sizing






SOLOLIFT2 WC-1

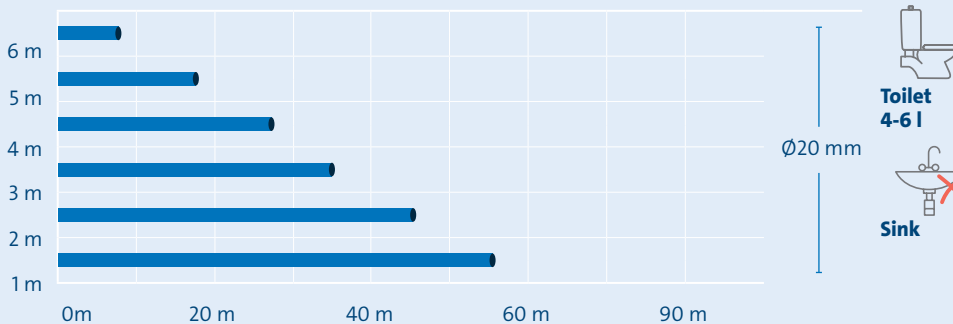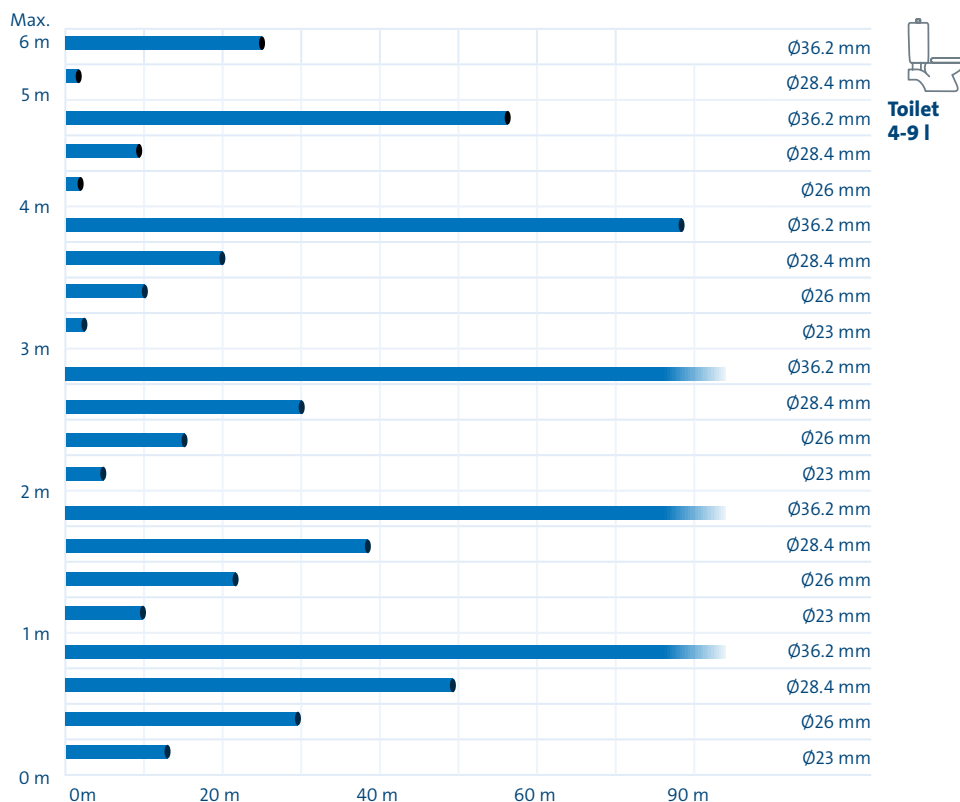

Lifting Stations – Quick sizing




 

SOLOLIFT2 WC-3

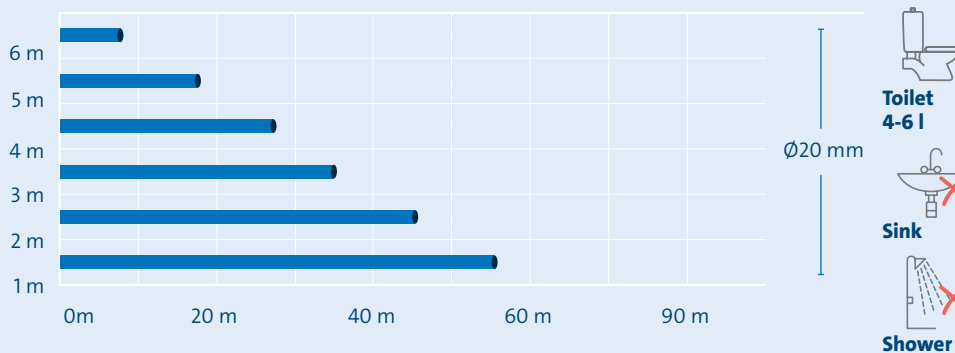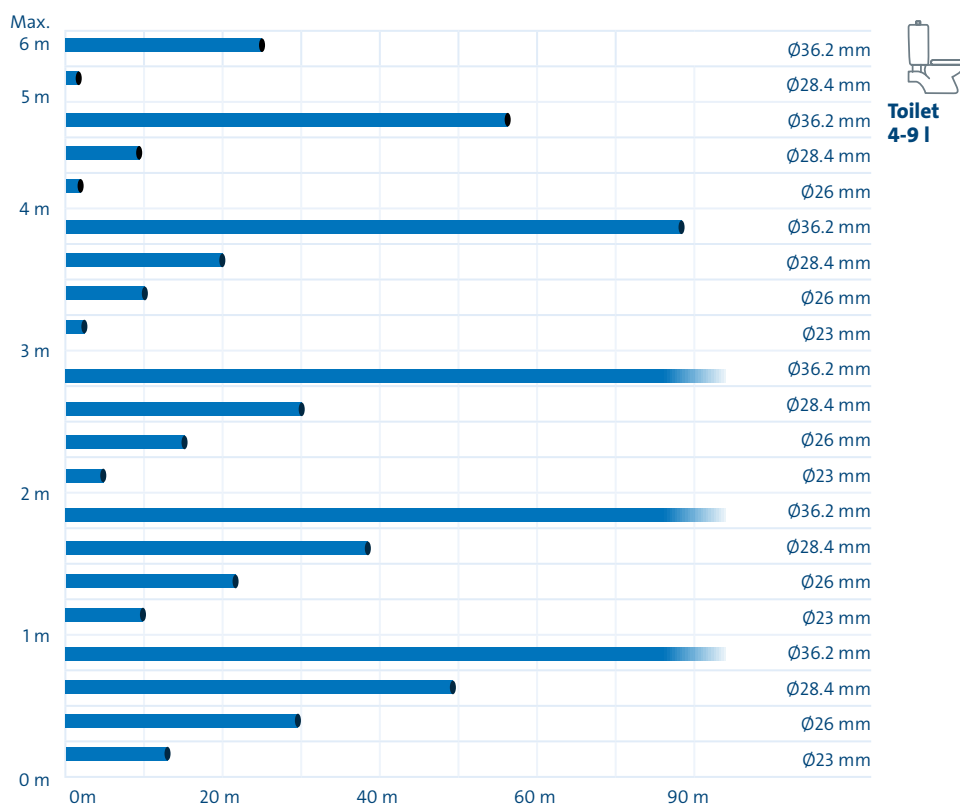


Lifting Stations – Quick sizing



 SOLOLIFT2 CWC-3

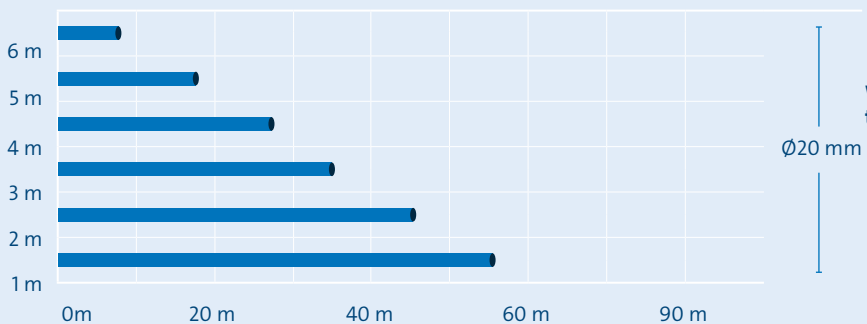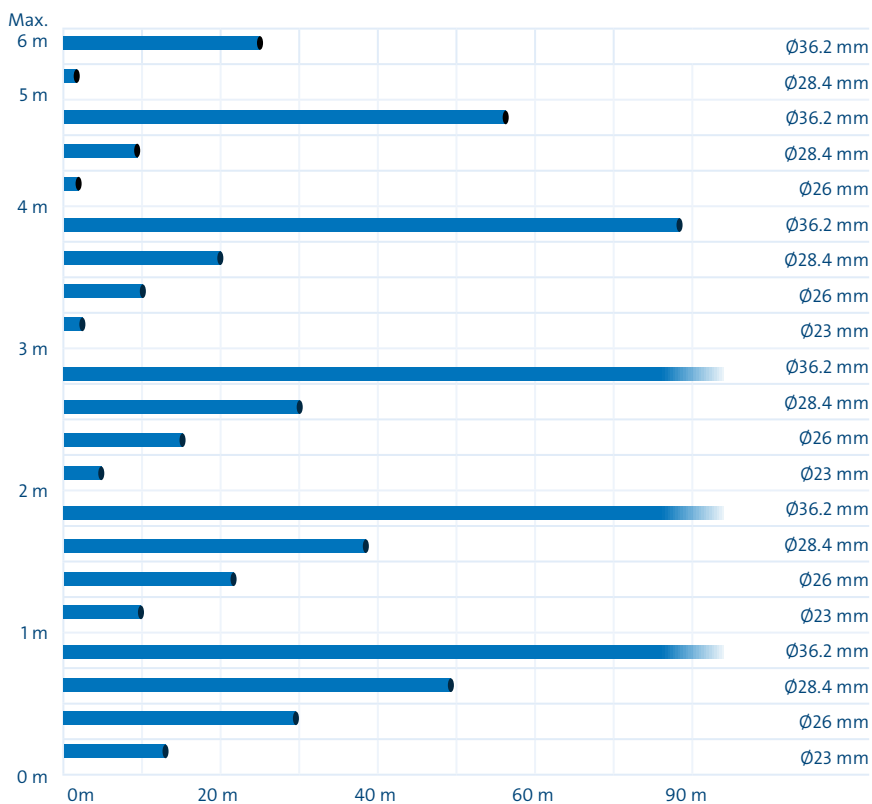

Lifting Stations – Quick sizing

 

SOLOLIFT2 C-3

		x										
6 m			9	13								Ø36.2 mm
	30	30										Ø28.4 mm
	14	14										Ø26 mm
	4											Ø23 mm
5 m												Ø20 mm
			31	35		3						Ø36.2 mm
	54	54	2.5	4								Ø28.4 mm
	30	30										Ø26 mm
4 m												Ø23 mm
												Ø20 mm
	13											Ø20 mm
	2	2.5										Ø20 mm
3 m												Ø20 mm
			53	58	8	14		0.5				Ø36.2 mm
	78	78	9	11								Ø28.4 mm
	45	45	2.5	4.5								Ø26 mm
2 m												Ø23 mm
												Ø20 mm
	21	21										Ø20 mm
	6.5	7										Ø20 mm
1 m												Ø20 mm
			76	80	19	24		7				Ø36.2 mm
	102	102	16	18	1.5	3						Ø28.4 mm
	61	61	7	9.5								Ø26 mm
0 m												Ø23 mm
												Ø20 mm
	30	30	2	2.5								Ø23 mm
	12	12										Ø20 mm
0 m												Ø20 mm
			98	102	29	35		13		3		Ø36.2 mm
	126	128	23	25	5	6.5		1				Ø28.4 mm
	77	76	12	14	1	2.5						Ø26 mm
0 m												Ø23 mm
												Ø20 mm
	39	39	5	5.5								Ø23 mm
	16	16	0.5	0.5								Ø20 mm
0 m												Ø20 mm
			120	124	38	46		20		7		Ø36.2 mm
	150	150	30	32	9	10		3.5		0.5		Ø28.4 mm
	92	92	17	19	3.5	5		1.5				Ø26 mm
0 m												Ø23 mm
												Ø20 mm
	47	47	8	8.5	1	1.5						Ø23 mm
	20	21	2.5	2.5								Ø20 mm
		0.5 l/s	1 l/s	1.5 l/s	2 l/s	2.5 l/s	3 l/s					



Lifting Stations – Quick sizing



SOLOLIFT2 D-2

4 m					Ø28.4 mm
3 m	6				Ø20 mm
		24			Ø28.4 mm
2 m	22	0.1			Ø20 mm
		47	3		Ø28.4 mm
1 m	37	4.5			Ø20 mm
		71	10		Ø28.4 mm
0 m	52	9.5			Ø20 mm
	0.25 l/s	0.5 l/s	1 l/s	1.5 l/s	