


ALPHA HWR








Max. 95 % RH
Enclosure type 2




 

Min./Max. 36 °F / 203 °F
(+2 °C / +95 °C) 





Max. 175 PSI
(12 bar) 




Min./Max. 32 °F / 131 °F
(0 °C / +55 °C) 


< (Lp) 25 dB(A) 





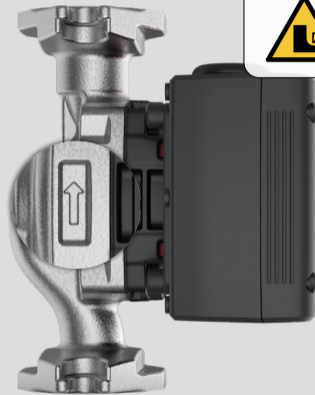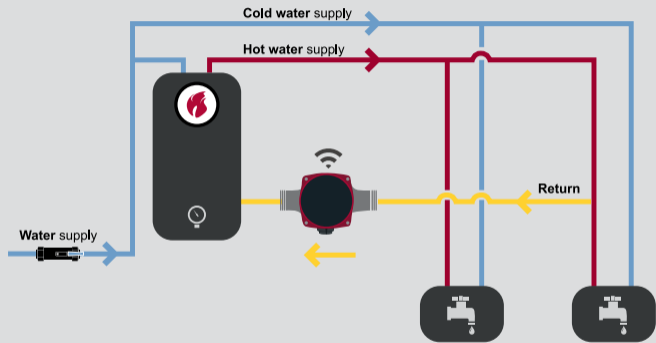

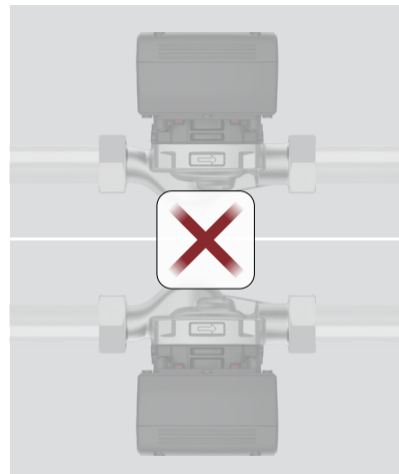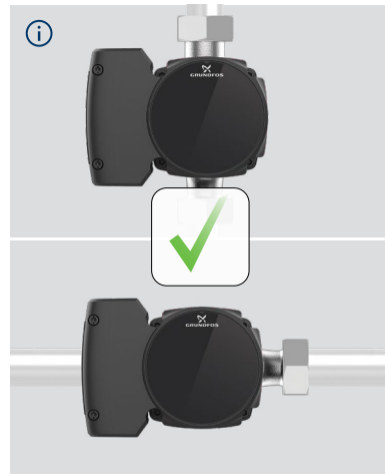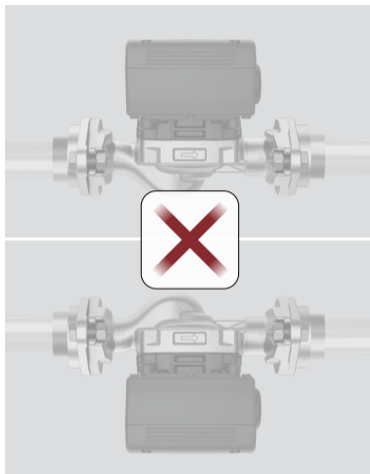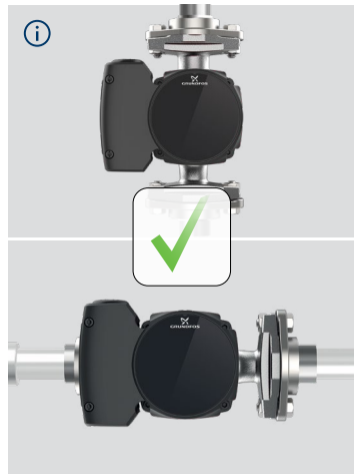

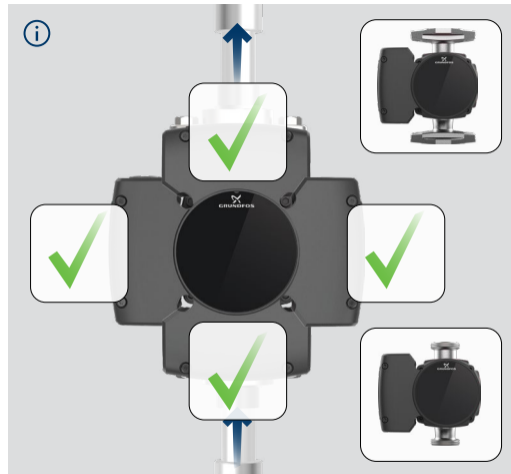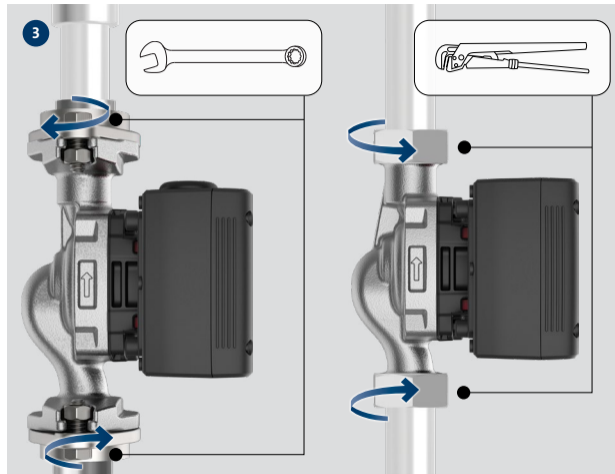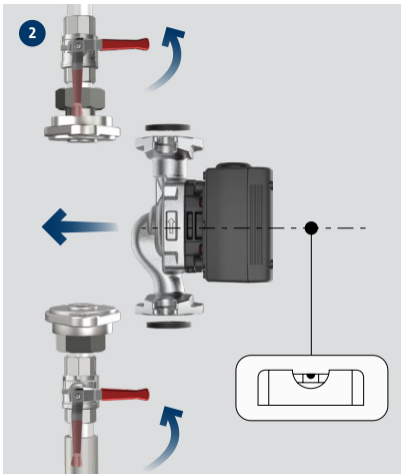

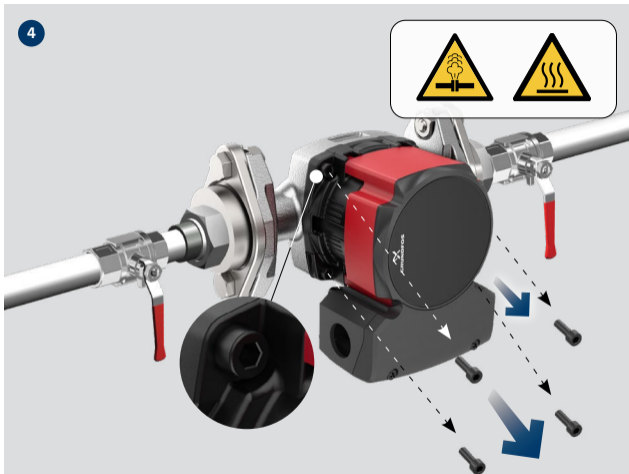

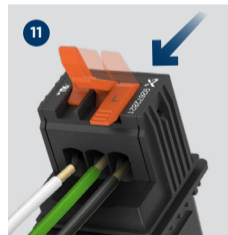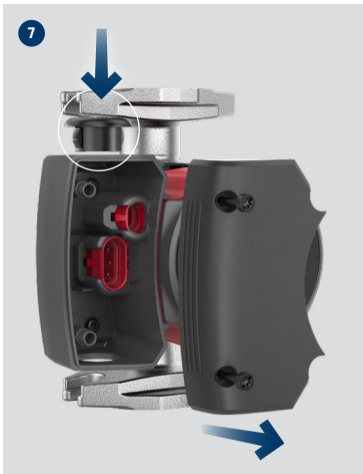



13

 
1 × 115 V ±10 %
~60 Hz ⚡






14




15



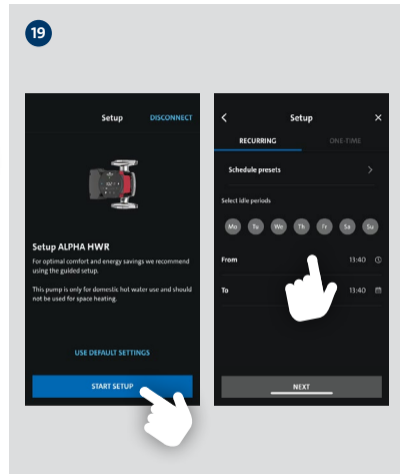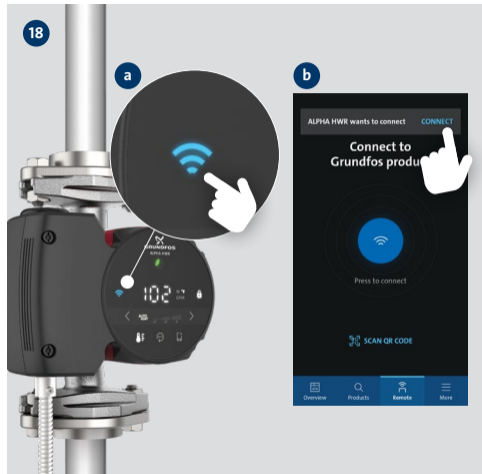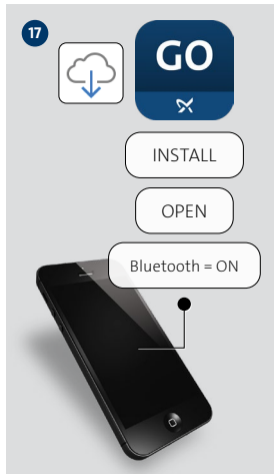

i **Fault finding**
Détection de défauts de fonctionnement
Búsqueda de fallas

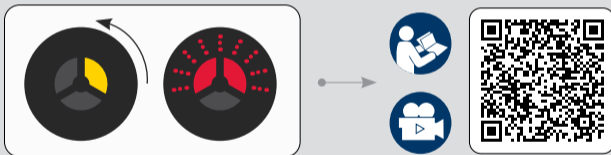

Canada

GRUNDFOS Canada inc.
2941 Brighton Road
Oakville, Ontario
L6H 6C9
Tel.: +1-905 829 9533
Fax: +1-905 829 9512

U.S.A.

GRUNDFOS Water Utility Headquarters
856 Koomey Road
Brookshire, Texas 77423 USA

GRUNDFOS CBS Inc.
902 Koomey Road
Brookshire, TX 77423 USA
Phone: 281-994-2700
Toll Free: 1-800-955-5847
Fax: 1-800-945-4777

GRUNDFOS Pumps Corporation
9300 Loiret Boulevard
Lenexa, Kansas 66219 USA
Tel.: +1 913 227 3400
Fax: +1 913 227 3500

Mexico

Bombas GRUNDFOS de México
S.A. de C.V.
Boulevard TLC No. 15
Parque industrial Stiva Aeropuerto
Apodaca, N.L. 66600
Tel.: +52-81-8144 4000
Fax: +52-81-8144 4010

Addresses Revised 04.2021



92719193 06.2023 / ECM: 1370343



(93)92719193

GRUNDFOS Holding A/S

Poul Due Jensens Vej 7
DK-8850 Bjerringbro
Tel: +45 87 50 14 00

www.grundfos.com

GRUNDFOS

Trademarks displayed in this material, including but not limited to Grundfos and the Grundfos logo are registered trademarks owned by The Grundfos Group. All rights reserved.

© 2023 Grundfos Holding A/S, all rights reserved.